

# Technical data sheet

## UP Flush-mounted outlet box

Item number: 2003732



Flush-mounted outlet box for single cable routing. Oval shape, for use in masonry with an installation depth of at least 35 mm.

- 2 entries up to  $\varnothing$  20 mm
- 1 combination entry of  $\varnothing$  10 and 20 mm
- 1 entry up to  $\varnothing$  20 mm in the base



**PP** Polypropylene

### Master data

Item number	2003732
Type	UG 30-WA-D
Description 1	UP Flush-mounted outlet box
Description 2	with cover
Available from	01.10.2021
Manufacturer	OBO
Dimension	$\varnothing$ 2x35mm, H35
Colour	Jet black
Material	Polypropylene
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.15 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0932 kg CO2e / 1 Piece



# Technical data sheet

## UP Flush-mounted outlet box

Item number: 2003732



### Dimensions

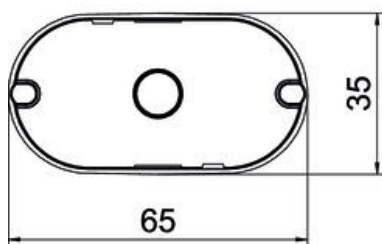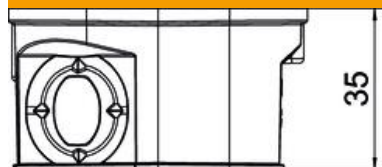

Length	65 mm
Width	35 mm
Height	35 mm

### Technical data

No. of entries	4
Type of entry	NYM cables, data cables and corrugated pipes
Type of housing penetration	Break-out opening
Version for	Miscellaneous
Type	Wall outlet box
Cover	White
Cover fastening	Locking
Entry from rear	yes
Flame-resistant	acc. to VDE 0471/IEC 60695-2-11, test temperature 650°C
Shape	Miscellaneous
for pipe diameter	20 mm
Halogen-free	yes
Max. Conductor cross-section	2.5 mm <sup>2</sup>
With nail strap	no
With bolts	no
Nominal cross-section, max.	2.5 mm <sup>2</sup>
Nominal cross-section, min.	1.5 mm <sup>2</sup>
Pipe entries Ø 20 mm	4
Impact-resistant	no
Protection rating	IP30
Airtight	no
Rated voltage	400 V