

Technical data sheet

UG60 device socket with square support

Item number: 2004372



The ideal system for use in any kind of masonry. The products were developed according to the state of the art and are perfectly matched. They can fulfil any practical requirements, thus allowing perfect installations in record time. The system comprises a comprehensive range of accessories and can be used for any application.



PS Polystyrene

Master data

Item number	2004372
Type	UG 60 258G
Description 1	Box, empty
Description 2	concealed, with square support
Manufacturer	OBO
Dimension	Ø60mm, H40mm
Colour	Black
Material	Polystyrene
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.3 kg
Weight unit	kg/100 pc.


Technical data sheet

UG60 device socket with square support

Item number: 2004372



Dimensions

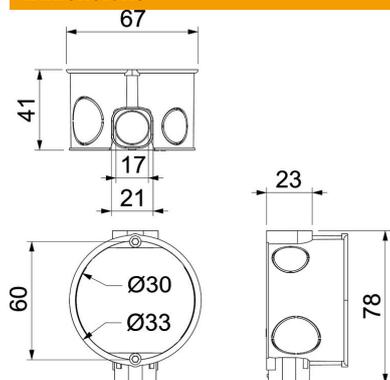

Height 40 mm

Technical data

No. of entries	7
Type of insertion...	Break-out openings for cables and pipes Ø 20 mm and Ø 25 mm
Version for	Single
Type	Device connection socket/box
Device fixing	Screw or spread
Equipment	Without
Cover	Without
Entries	7
Flame-resistant	acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C
Shape	Round
Floor height, min.	42 mm
for pipe diameter	20/25 mm
Accessory screw clearance	60 mm
With bolts	no
Mounting type	Concealed
Nominal cross-section, max.	2.5 mm ²
Nominal cross-section, min.	1.5 mm ²
Sealable	no
Protection rating	IP20
Support	Square support
Rated voltage	400 V