


# Technical data sheet

## UKL8 KR with 4x mounting support

Item number: 7429665

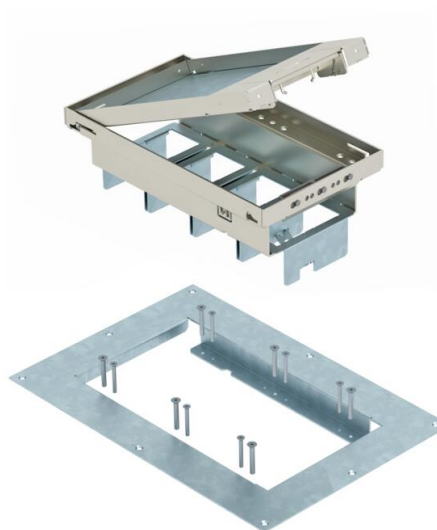

Height-adjustable cassette with cord outlet for direct installation in false ceilings for indoor use.

The scope of delivery contains a mounting lid and four mounting supports, each for two Modul 45 devices.



A2 Stainless steel

### Master data

|                                    |                             |
|------------------------------------|-----------------------------|
| Item number                        | 7429665                     |
| Type                               | UKL8 KR                     |
| Description 1                      | Cassette construction set   |
| Description 2                      | for cavity ceiling mounting |
| Manufacturer                       | OBO                         |
| Material                           | Stainless steel 1.4301      |
| Smallest sales unit                | 1                           |
| Unit of quantity                   | Piece                       |
| Weight                             | 404 kg                      |
| Weight unit                        | kg/100 pc.                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 21,9803 kg CO2e / 1 Piece   |


# Technical data sheet

## UKL8 KR with 4x mounting support

Item number: 7429665



### Dimensions

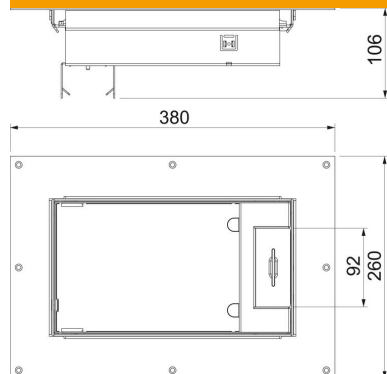

|        |        |
|--------|--------|
| Length | 380 mm |
| Width  | 260 mm |
| Height | 106 mm |

### Technical data

|                               |                         |
|-------------------------------|-------------------------|
| Number of installable devices | 8                       |
| Number of mounting boxes      | 4                       |
| Cable outlet version          | Swivellable cord outlet |
| Floor covering thickness      | 15 mm                   |