

Technical data sheet

US 3 support A4

Item number: 6342491



U support in fixed lengths. Dimensions 30 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 25.



A4 Stainless steel

2B Bright, treated

Master data

Item number	6342491
Type	US 3 100 A4
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x30x1000
Colour	stainless steel
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	132 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	7,9057 kg CO2e / 1 Piece


Technical data sheet

US 3 support A4

Item number: 6342491



Dimensions

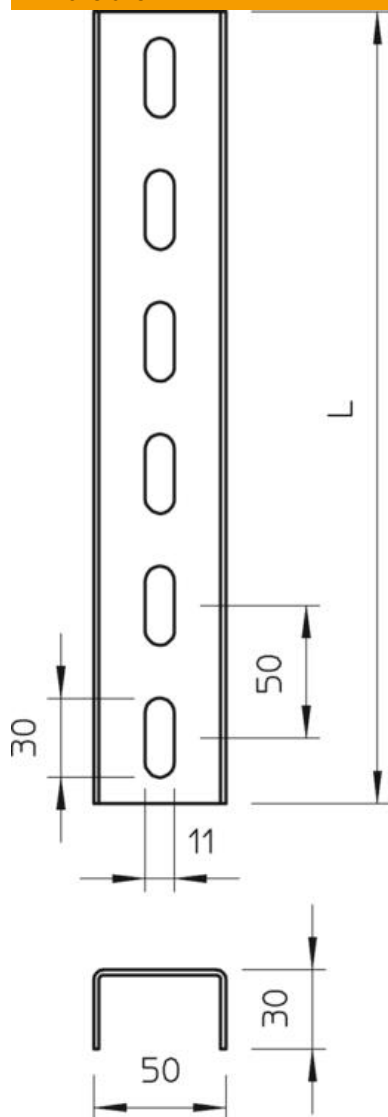

Dimension	30 x 50 x 2,0
Length	1,000 mm
Width	50 mm
Height	30 mm

Technical data sheet

US 3 support A4

Item number: 6342491



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	no
Material thickness	2 mm
With tothing	no
Profile shape	U profile
Static value A	1.42 cm ²
Static value I _y	1.52 cm ⁴
Static value I _z	5.72 cm ⁴
Static value W _y	0.7 cm ³
Static value W _z	2.29 cm ³