

Technical data sheet

US 5 support A4

Item number: 6341055



U support in fixed lengths. Dimensions 50 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 45.



A4 Stainless steel

2B Bright, treated

Master data

Item number	6341055
Type	US 5 40 A4
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x50x400
Colour	stainless steel
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	97 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	5,4544 kg CO2e / 1 Piece


Technical data sheet

US 5 support A4


Item number: 6341055



Dimensions

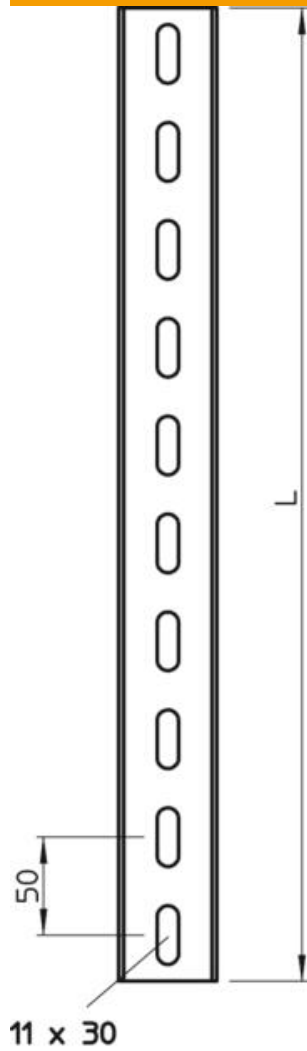

Dimension	50 x 50 x 2,5
Length	400 mm
Width	50 mm
Height	50 mm

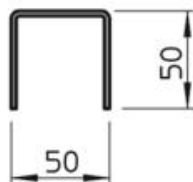

Technical data sheet

US 5 support A4

Item number: 6341055



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	no
Material thickness	2.5 mm
With tothing	no
Profile shape	U profile
Static value A	2.74 cm ²
Static value I _y	8.32 cm ⁴
Static value I _z	12.53 cm ⁴
Static value W _y	2.61 cm ³
Static value W _z	5.01 cm ³