

# Technical data sheet

## US 5 support A4

Item number: 6341059



U support in fixed lengths. Dimensions 50 x 50 mm.  
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 45.



**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6341059
Type	US 5 60 A4
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x50x600
Colour	stainless steel
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	145 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	8,2015 kg CO2e / 1 Piece


# Technical data sheet

US 5 support A4

Item number: 6341059



## Dimensions

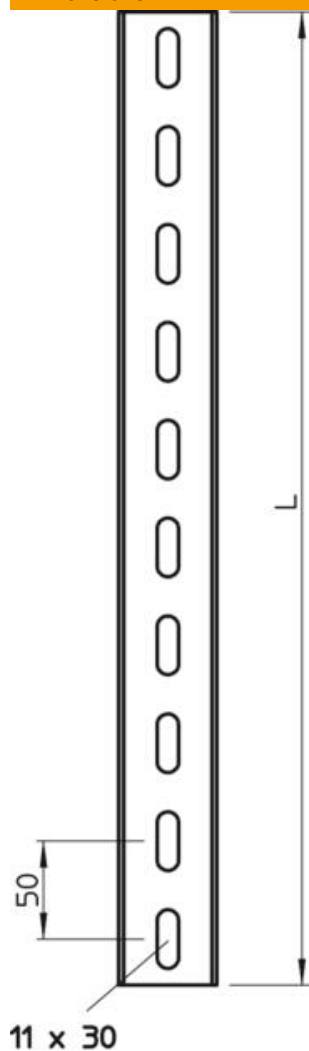

Dimension	50 x 50 x 2,5
Length	600 mm
Width	50 mm
Height	50 mm

# Technical data sheet

US 5 support A4

Item number: 6341059



## Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	no
Material thickness	2.5 mm
With tothing	no
Profile shape	U profile
Static value A	2.74 cm <sup>2</sup>
Static value I <sub>y</sub>	8.32 cm <sup>4</sup>
Static value I <sub>z</sub>	12.53 cm <sup>4</sup>
Static value W <sub>y</sub>	2.61 cm <sup>3</sup>
Static value W <sub>z</sub>	5.01 cm <sup>3</sup>