


Technical data sheet

UZD350-4 junction and branch box

Item number: 7410076

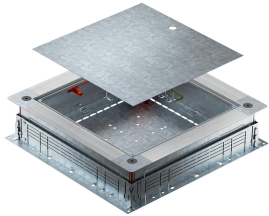

Junction and branch box for screed-covered underfloor installation duct with sheet steel side walls. For mounting of installation units in the mounting lid (to be ordered separately). Can be adjusted continuously to a nominal screed height of 120–165 mm using the quick height-adjustment unit. The screed can be worked up to be flush with the screed edge. With an acoustic decoupling option after screed laying, and with system accessories, it can be used for heavy-duty applications. Insertion of cables with the 2-part EÜK duct.



St

Steel

FS

Strip galvanised

Master data

Item number	7410076
Type	UZD350-4 120165
Description 1	Junction and branch box
Description 2	for screed height 120-165 mm
Manufacturer	OBO
Dimension	500x480x120
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	431 kg
Weight unit	kg/100 pc.


Technical data sheet

UZD350-4 junction and branch box

Item number: 7410076



Dimensions

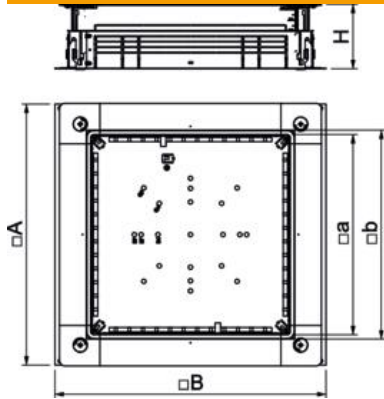

Length	480 mm
Width	500 mm
Height	120 mm
Dimension a	362 mm
Dimension A	480 mm
Dimension B	500 mm
Dimension b	383 mm

Technical data

Floor plate	yes
Cover version	Universal
Seal installation option	yes
Installation opening for on-floor tank	no
Decouplable	yes
Screed height, max.	165 mm
Screed height, min.	120 mm
For pipe connection	no
Suitable for screed-flush closed underfloor ducts	no
Suitable for screed-covered underfloor ducts	yes
Suitable for underfloor ducts	yes
Trunking width, max.	350 mm
Trunking width, min.	190 mm
Trunking height, max.	58 mm
Duct height, min.	28 mm
Minimum screed height	80
Nominal size	350 mm
Height-adjustment range, max.	165 mm
Height-adjustment range, min.	120 mm