

Technical data sheet

UZD350-3 for screed height 70–125 mm

Item number: 7410034



Underfloor junction and branch box for screed-covered underfloor installation ducts with sheet steel side walls. To mount installation units in the mounting lid (to be ordered separately). Height can be infinitely adjusted to the nominal screed height (rapid adjustment possible) and the screed can be worked flush to the screed scraping edge. With noise decoupling option after screed laying and can be used with system accessories, also for heavy-duty application. Side walls prepared for duct widths of 190, 250 and 350 mm.



- St** Steel
- FS** Strip galvanized

Master data

Item number	7410034
Type	UZD 350-3
Description 1	Junction and branch box
Description 2	for screed height 70-125mm
Manufacturer	OBO
Dimension	510x467x70
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	590 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	9,6452 kg COe / 1 Piece


Technical data sheet

UZD350-3 for screed height 70–125 mm

Item number: 7410034



Dimensions

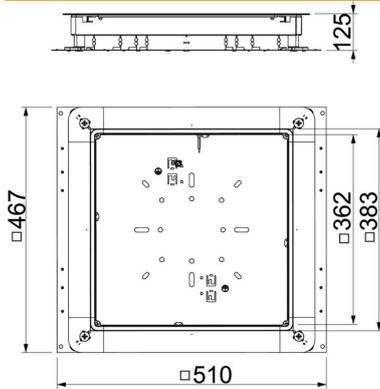

Dimension a	362 mm
Dimension A	467 mm
Dimension B	510 mm
Dimension b	383 mm

Technical data

Floor plate	yes
Cover version	Universal
Seal installation option	yes
Installation opening for on-floor tank	no
Decouplable	yes
Screed height, max.	125 mm
Screed height, min.	70 mm
For pipe connection	no
Suitable for screed-flush closed underfloor ducts	no
Suitable for screed-covered underfloor ducts	yes
Trunking width, max.	350 mm
Trunking width, min.	190 mm
Trunking height, max.	48 mm
Duct height, min.	28 mm
Minimum screed height	70
Nominal size	350 mm
Height-adjustment range, max.	125 mm
Height-adjustment range, min.	70 mm