

Technical data sheet

Steel wire tensioning rope

Item no. 5303206



Steel wire tensioning rope, galvanised with fibre inlay (hemp core).
Cable Ø 2–6 mm: round-stranded cable 6 x 7 according to DIN 3055.
Cable Ø 8–10 mm: round-stranded cable 6 x 19 according to DIN 3060.
Minimum break force 1770 N/mm².




St	Steel
G	Electrogalvanised


Master data

Item no.	5303206
Type	957 3 G
Description 1	Steel wire tensioning cable
Description 2	with hemp core
Dimension	3mm
Material	Steel
Material symbol	St
Surface	Electrogalvanised
Surface to DIN	EN ISO 19598 / EN ISO 4042
Surface symbol	G
Smallest sales unit (VG)	50 m
Weight	3,22 kg/100 m

Technical data

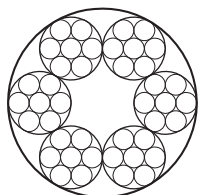

6x7

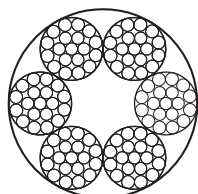

6x19

Breaking load	5,29 kN
Breaking load	5.290,00 N
in rings	50,00 m
Cable diameter	3,00 mm