


Technical data sheet

HW Cavity wall outlet box, double, airtight

Item no. 2003834

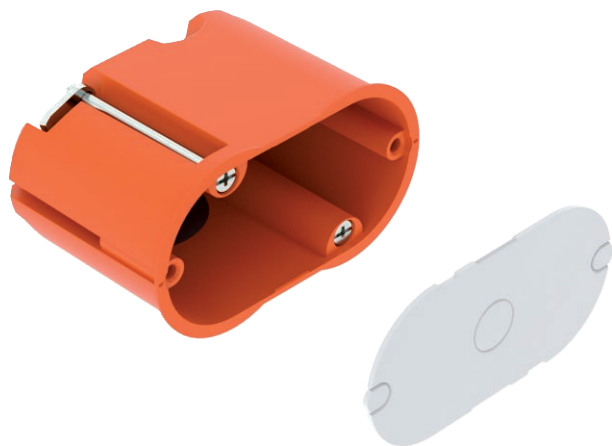

Airtight, double wall outlet box for cavity walls, for the mounting of wall luminaires or loudspeakers With cover.

- 1 entry for NYM cables 3 x 2.5 mm² or 5 x 1.5 mm²
- 2 entries for NYM cables 3 x 1.5 mm²
- 1 combination pipe entry for Ø 20 and 25 mm

Tested according to DIN EN 60670-1, DIN EN 60670-22 and DIN 49073-1.




PP/TPE Polypropylene / thermoplastic elastomer

Master data

Item no.	2003834
Type	HG 45-WAD-LD
Description 1	HW Cavity wall outlet box
Description 2	airtight, double combination
Available from	01.10.2021
Dimension	68x38x45
Colour	Orange / grey
Material	Polypropylene / thermoplastic elastomer
Material symbol	PP/TPE
Smallest sales unit (VG)	25 Piece
Weight	1,93 kg/100 pc.

Technical data

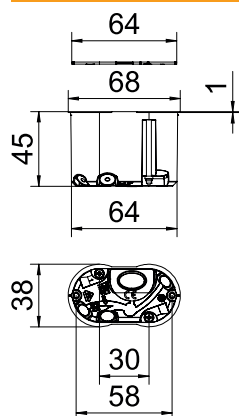

Width	38,00 mm
Height	45,00 mm
Length	68,00 mm
No. of entries	4
Type of entry	NYM cables and pipes
Type of housing penetration	Insertion membrane
Version for	Double
Shape	Wall outlet socket
Fastening type	Fastening with bolt
Device fixing	Screws ,
Cover	White
Cover fastening	Locking
Milling hole diameter	35,00 mm
Flame-resistant	acc. to VDE 0471/IEC 60695-2-11, test temperature 850°C
Shape	Oval
For pipe diameter	20/25 mm
Combination entries Ø 20 / 25 mm	1
Cable entries 3 x 2.5 mm ² / 5 x 1.5 mm ²	1
Cable entries 3 x 1.5 mm ²	2
Suitable for board thickness	5,00 - 40,00 mm
Halogen-free	<input checked="" type="checkbox"/>
With bolts	<input type="checkbox"/>
Nominal cross section	1,50 - 1,50 mm ²
Rated voltage	400,00 V
Impact-resistant	<input checked="" type="checkbox"/>

Technical data sheet

HW Cavity wall outlet box, double, airtight

Item no. 2003834



Technical data

Protection rating	IP30
Airtight	<input checked="" type="checkbox"/>