


# Technical data sheet

## U support connector A2

Item number: 6018408



U support connector to connect US 7 supports.  
Including appropriate fastening material.

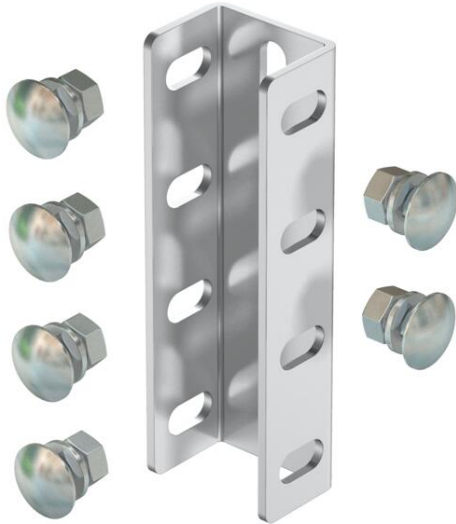

A2	Stainless steel
2B	Bright, treated

### Master data

Item number	6018408
Type	VUS 7 A2
Description 1	U support connector
Description 2	including truss-head bolts
Manufacturer	OBO
Dimension	190x61
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	110.9 kg
Weight unit	kg/100 pc.


# Technical data sheet

## U support connector A2

Item number: 6018408



### Dimensions

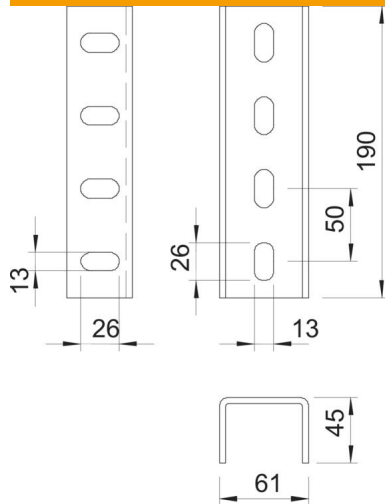

Dimension	61 x 45 x 190
Length	190 mm
Width	61 mm
Height	45 mm

### Technical data

Type of perforation	3 sides perforated
Version for	Internal connector
Drill hole spacing, centre	50 mm
Suitable for profile shapes	U profile
Hole size	13 x 26 mm
Material thickness	4 mm
With screw accessories	yes
Profile shape	U profile
Rustproof steel, pickled	yes