

Technical data sheet

Trunking, type WDK 40060

Item number: 6025638



Trunking cover and base with base perforation.
During installation, ensure that only halogen-free accessories and fastening materials are used.
Four cover fixing devices included.
Lid clamp can be moved along the entire length of the trunking.



PVC Polyvinylchloride

Master data

Item number	6025638
Type	WDK40060SW
Description 1	Wall trunking system
Description 2	with base perforation
Manufacturer	OBO
Dimension	2000x60x40
Colour	Jet black; RAL 9005
Material	Polyvinylchloride
Smallest sales unit	32
Unit of quantity	Metre
Weight	55.4 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,1648 kg CO2e / 1 Meter


Technical data sheet

Trunking, type WDK 40060

Item number: 6025638



Dimensions

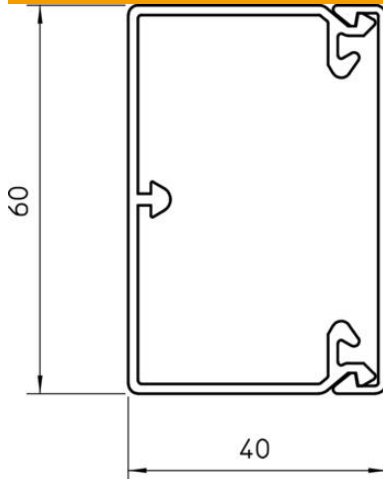

Length	2,000 mm
Width	60 mm
Height	40 mm

Technical data

Number of fixed partitions	0
Number of cables NYM 3 x 1.5 mm ² Ø 10.5 mm (without socket)	10
Number of cables NYM 3 x 2.5 mm ² Ø 11.5 mm (without socket)	8
Number of cables NYM 5 x 1.5 mm ² Ø 12.0 mm (without socket)	7
Number of insertable partitions	1
Version, cable trunking cover	Loose
Fastening type	Base perforation
Maintain electrical functions	no
Halogen-free	no
Cable retaining clip	yes
Duct connector	no
Delivery on a roll	no
Usable cross-section	1775 mm ²
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C