

Technical data sheet

Trunking, type WDK 60110

Item number: 6021840



Trunking cover and base with base perforation.
Four cover fixing devices included.
Lid clamp can be moved along the entire length of the trunking.



PVC Polyvinylchloride

Master data

Item number	6021840
Description 1	Wall trunking system
Description 2	with base perforation
Manufacturer	OBO
Dimension	60x110x2000
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	16
Unit of quantity	Metre
Weight	117 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	1,9596 kg COe / 1 Meter


Technical data sheet

Trunking, type WDK 60110

Item number: 6021840



Dimensions

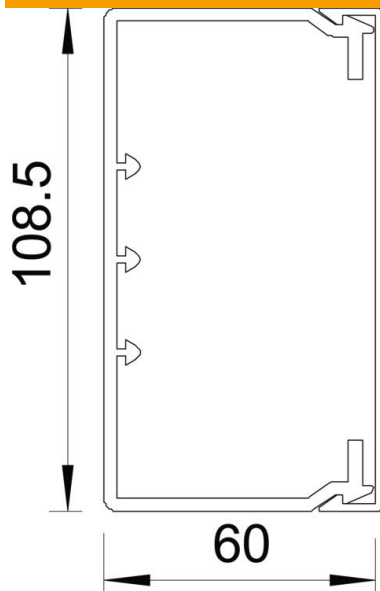

Length	2,000 mm
Width	108.5 mm
Height	60.3 mm

Technical data

Number of fixed partitions	0
Number of cables NYM 3 x 1.5 mm ² Ø 10.5 mm (without socket)	29
Number of cables NYM 3 x 2.5 mm ² Ø 11.5 mm (without socket)	24
Number of cables NYM 5 x 1.5 mm ² Ø 12.0 mm (without socket)	22
Number of insertable partitions	1
Version, cable trunking cover	Loose
Fastening type	Base perforation
Maintain electrical functions	no
Halogen-free	no
Cable retaining clip	yes
Duct connector	no
Delivery on a roll	no
Usable cross-section	5076 mm ²
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C