

Technical data sheet

Trunking, type WDK 60110

Item number: 6191215



Trunking cover and base with base perforation.
Four cover fixing devices included.
Lid clamp can be moved along the entire length of the trunking.



PVC Polyvinylchloride

Master data		
Item number	6191215	
Description 1	Wall trunking system	
Description 2	with base perforation	
Manufacturer	OBO	
Dimension	60x110x2000	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	16	
Unit of quantity	Metre	
Weight	117 kg	
Weight unit	kg/100 m	
CO Footprint (GWP) Cradle-to-Gate	1,9499 kg COe / 1 Meter	


Technical data sheet

Trunking, type WDK 60110

Item number: 6191215



Dimensions

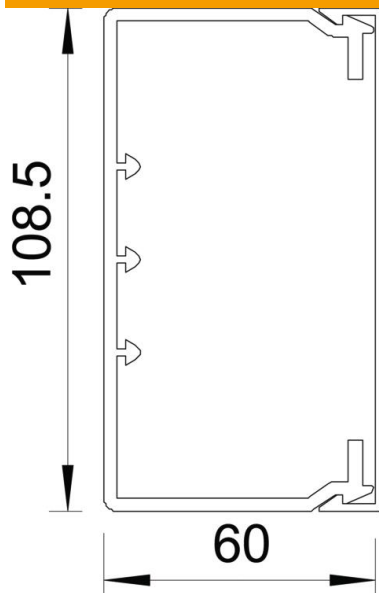

Length	2,000 mm
Width	108.5 mm
Height	60.3 mm

Technical data

Number of fixed partitions	0
Number of cables NYM 3 x 1.5 mm ² Ø 10.5 mm (without socket)	29
Number of cables NYM 3 x 2.5 mm ² Ø 11.5 mm (without socket)	24
Number of cables NYM 5 x 1.5 mm ² Ø 12.0 mm (without socket)	22
Number of insertable partitions	1
Version, cable trunking cover	Loose
Fastening type	Base perforation
Maintain electrical functions	no
Halogen-free	no
Cable retaining clip	yes
Duct connector	no
Delivery on a roll	no
Usable cross-section	5076 mm ²
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C