

# Technical data sheet

## T piece cover, for trunking type WDKH 20020

Item number: 6176072



T and intersection cover for changing the direction of the halogen-free WDK-H trunking.



**PC/ABS** Polycarbonate/Acrylnitrile-butadiene-styrene

### Master data

Item number	6176072
Type	WDKH-T20020LGR
Description 1	T piece hood
Description 2	halogen-free
Manufacturer	OBO
Dimension	20x20mm
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	4
Unit of quantity	Piece
Weight	0.659 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0479 kg CO2e / 1 Piece


# Technical data sheet

T piece cover, for trunking type WDKH 20020

Item number: 6176072



## Dimensions

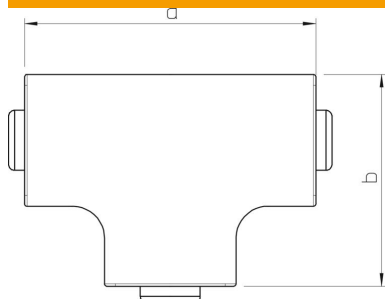

Length	57 mm
Width	20 mm
Height	20 mm
Dimension a	57 mm
Dimension b	39 mm

## Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	yes
Trunking depth	20 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK07.
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C