

Technical data sheet

T and intersection cover, for trunking type WDKH 40060

Item number: 6176080



T and intersection cover for changing the direction of the halogen-free WDKH trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.




Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6176080
Type	WDKH-T40060LGR
Description 1	T- and crosspiece cover
Description 2	halogen-free
Manufacturer	OBO
Dimension	40x60mm
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	2
Unit of quantity	Piece
Weight	8.413 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,6468 kg CO2e / 1 Piece

Dimensions

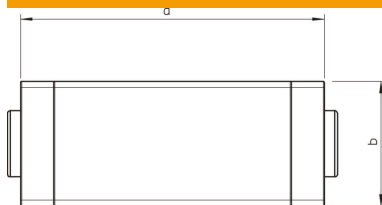

Length	190 mm
Width	65 mm
Height	40 mm
Dimension a	190 mm
Dimension b	66 mm

Technical data sheet

T and intersection cover, for trunking type WDKH 40060

Item number: 6176080



Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	40x60
Halogen-free	yes
Duct height, min.	60 mm
Trunking depth	40 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK07.
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C