


Technical data sheet

End piece, trunking type WDK 100130

Item number: 6183956

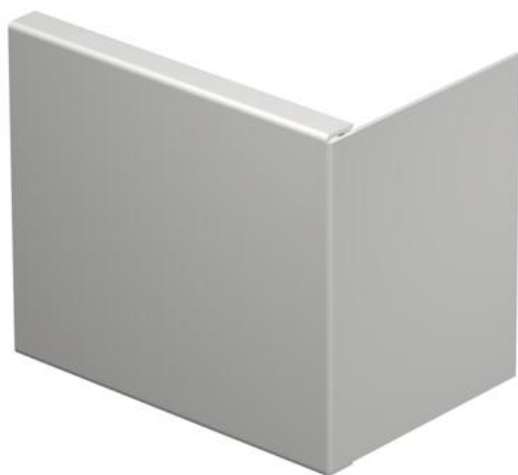

End piece to close the WDK trunking.
The end pieces are pushed onto the WDK trunking in the same way as the covers.



PVC Polyvinylchloride

Master data

Item number	6183956
Type	WDK HE100130LGR
Description 1	End piece
Manufacturer	OBO
Dimension	100x130mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	8.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3413 kg CO2e / 1 Piece


Technical data sheet

End piece, trunking type WDK 100130

Item number: 6183956



Dimensions

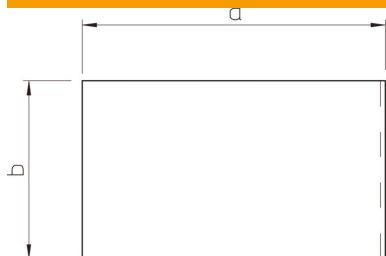

Length	150 mm
Width	130 mm
Height	100 mm
Dimension a	150 mm
Dimension b	130 mm
Dimension H	130 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C