

# Technical data sheet

## End piece, trunking type WDK 15015

Item number: 6183603



End piece to close the WDK trunking.  
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.




**PVC** Polyvinylchloride

### Master data

Item number	6183603
Type	WDK HE15015LGR
Description 1	End piece
Manufacturer	OBO
Dimension	15x15mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.081 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0168 kg CO2e / 1 Piece

### Dimensions

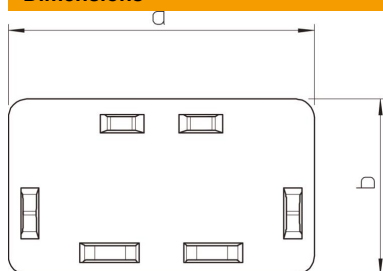

Length	11.5 mm
Width	15 mm
Height	15 mm
Dimension a	15 mm
Dimension b	15 mm
Dimension H	15 mm

# Technical data sheet

End piece, trunking type WDK 15015

Item number: 6183603



## Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C