

Technical data sheet

End piece, trunking type WDK 20020

Item number: 6183611



End piece to close the WDK trunking.
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.




PVC Polyvinylchloride

Master data

Item number	6183611
Type	WDK HE20020LGR
Description 1	End piece
Manufacturer	OBO
Dimension	20x20mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.101 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0091 kg CO2e / 1 Piece

Dimensions

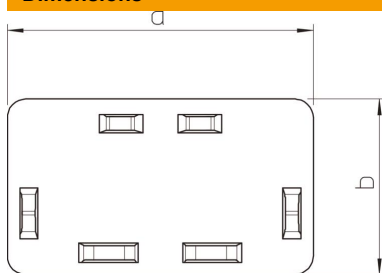

Length	11.5 mm
Width	17 mm
Height	17 mm
Dimension a	17 mm
Dimension b	17 mm
Dimension H	20 mm

Technical data sheet

End piece, trunking type WDK 20020

Item number: 6183611



Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C