


# Technical data sheet

End piece, trunking type WDK 20035

Item number: 6162487



End piece to close the WDK trunking.  
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.

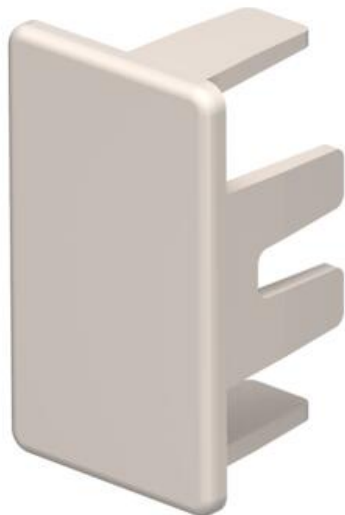

**PVC** Polyvinylchloride

## Master data

Item number	6162487
Type	WDK HE20035CW
Description 1	End piece
Manufacturer	OBO
Dimension	20x35mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.334 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0284 kg CO2e / 1 Piece

# Technical data sheet

End piece, trunking type WDK 20035

Item number: 6162487



## Dimensions



Length	17 mm
Width	35 mm
Height	20 mm
Dimension a	35 mm
Dimension b	20 mm
Dimension H	35 mm

## Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C