


Technical data sheet

End piece, trunking type WDK 25025

Item number: 6162533

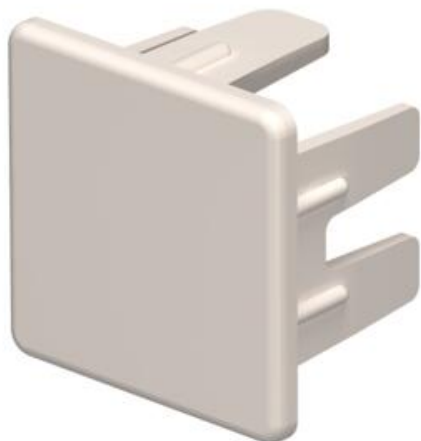

End piece to close the WDK trunking.
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.



PVC Polyvinylchloride

Master data

| | |
|------------------------------------|--------------------------|
| Item number | 6162533 |
| Type | WDK HE25025CW |
| Description 1 | End piece |
| Manufacturer | OBO |
| Dimension | 25x25mm |
| Colour | Cream; RAL 9001 |
| Material | Polyvinylchloride |
| Smallest sales unit | 10 |
| Unit of quantity | Piece |
| Weight | 0.303 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0124 kg CO2e / 1 Piece |

Technical data sheet

End piece, trunking type WDK 25025

Item number: 6162533



Dimensions



| | |
|-------------|-------|
| Length | 17 mm |
| Width | 25 mm |
| Height | 25 mm |
| Dimension a | 25 mm |
| Dimension b | 25 mm |
| Dimension H | 25 mm |

Technical data

| | |
|-----------------------------------|------------|
| Version for | Left/right |
| Fastening type | Lockable |
| Maintain electrical functions | no |
| Halogen-free | no |
| Protection rating | IP30 |
| Protective film | no |
| Protection rating IK code | IK04 |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -5 °C |