


# Technical data sheet

End piece, trunking type WDK 30030

Item number: 6183697

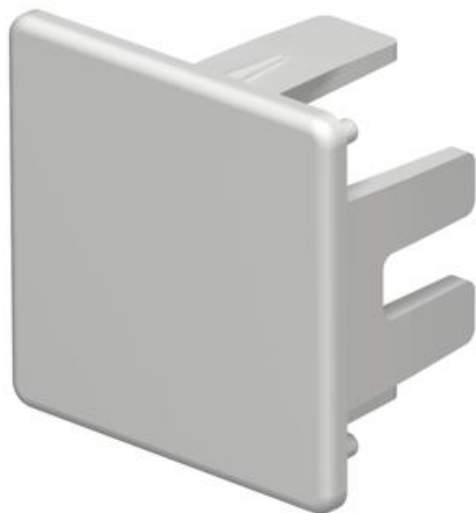

End piece to close the WDK trunking.  
The end pieces are pushed onto the WDK trunking and are fixed on the connector.



**PVC** Polyvinylchloride

## Master data

Item number	6183697
Type	WDK HE30030LGR
Description 1	End piece
Manufacturer	OBO
Dimension	30x30mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.365 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0191 kg CO2e / 1 Piece

# Technical data sheet

End piece, trunking type WDK 30030

Item number: 6183697



## Dimensions



Length	17 mm
Width	30 mm
Height	30 mm
Dimension a	30 mm
Dimension b	30 mm
Dimension H	30 mm

## Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C