


# Technical data sheet

End piece, trunking type WDK 40090

Item number: 6193234

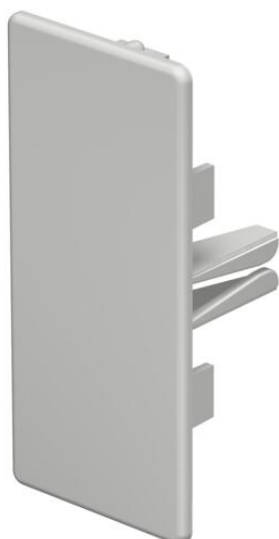

End piece to close the WDK trunking.  
The end pieces are pushed onto the trunking and kept in place by the spring action.



**PVC** Polyvinylchloride

## Master data

Item number	6193234
Type	WDK HE40090RW
Description 1	End piece
Manufacturer	OBO
Dimension	40x90mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	1.576 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0644 kg CO2e / 1 Piece

# Technical data sheet

End piece, trunking type WDK 40090

Item number: 6193234



## Dimensions



Length	27.5 mm
Width	90 mm
Height	40 mm
Dimension a	90 mm
Dimension b	40 mm
Dimension H	90 mm

## Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C