

Technical data sheet

End piece, trunking type WDK 60060

Item number: 6022499



End piece to close the WDK trunking.
The end pieces are pushed onto the trunking and kept in place by the spring action.



PVC Polyvinylchloride

Master data		
Item number	6022499	
Type	WDK HE60060GR	
Description 1	End piece	
Manufacturer	OBO	
Dimension	60x60mm	
Colour	Stone grey; RAL 7030	
Material	Polyvinylchloride	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	1.544 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0636 kg CO2e / 1 Piece	


Technical data sheet

End piece, trunking type WDK 60060

Item number: 6022499



Dimensions

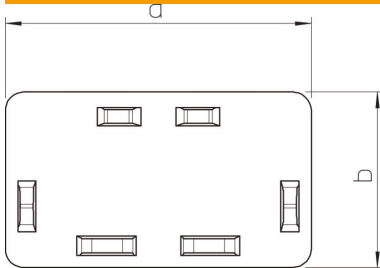

Length	27.5 mm
Width	60 mm
Height	60 mm
Dimension a	60 mm
Dimension b	60 mm
Dimension H	60 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C