

Technical data sheet

End piece, trunking type WDK 60210

Item number: 6022561



End piece to close the WDK trunking.
The end pieces are pushed onto the trunking and kept in place by the spring action.



PVC

 Polyvinylchloride

Master data		
Item number	6022561	
Type	WDK HE60210GR	
Description 1	End piece	
Manufacturer	OBO	
Dimension	60x210mm	
Colour	Stone grey; RAL 7030	
Material	Polyvinylchloride	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	5.479 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1713 kg CO2e / 1 Piece	


Technical data sheet

End piece, trunking type WDK 60210

Item number: 6022561



Dimensions

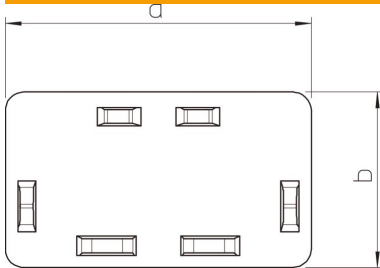

Length	27.5 mm
Width	210 mm
Height	60 mm
Dimension a	210 mm
Dimension b	60 mm
Dimension H	210 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C