


Technical data sheet

End piece, trunking type WDK 80170

Item number: 6183913

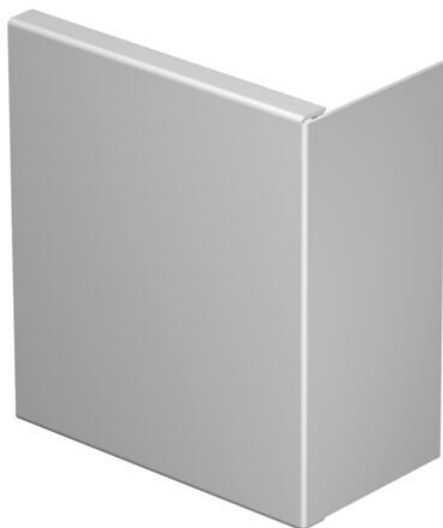

End piece to close the WDK trunking.
The end pieces are pushed onto the WDK trunking in the same way as the covers.



PVC Polyvinylchloride

Master data

Item number	6183913
Type	WDK HE80170LGR
Description 1	End piece
Manufacturer	OBO
Dimension	80x170mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	11.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3912 kg CO2e / 1 Piece


Technical data sheet

End piece, trunking type WDK 80170

Item number: 6183913



Dimensions

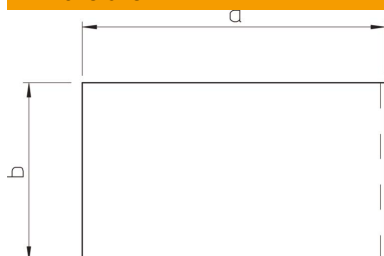

Length	150 mm
Width	170 mm
Height	80 mm
Dimension a	150 mm
Dimension b	170 mm
Dimension H	170 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C