

Technical data sheet

End piece, trunking type WDK 80210

Item number: 6024874



End piece to close the WDK trunking.
The end pieces are pushed onto the WDK trunking in the same way as the covers.



PVC Polyvinylchloride

Master data

Item number	6024874
Type	WDK HE80210GR
Description 1	End piece
Manufacturer	OBO
Dimension	80x210mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	14.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4322 kg CO2e / 1 Piece


Technical data sheet

End piece, trunking type WDK 80210

Item number: 6024874



Dimensions

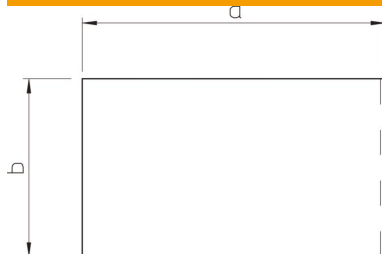

Length	150 mm
Width	210 mm
Height	80 mm
Dimension a	150 mm
Dimension b	210 mm
Dimension H	210 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C