

Technical data sheet

Flat angle cover, for duct type WDK 13025

Item number: 6192740



Flat angle hood for changing the direction of the WDK trunking.



PC/ABS Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6192740
Type	WDK HF13025PW
Description 1	Flat angle cover
Description 2	with coupling for raised floor
Manufacturer	OBO
Dimension	15x50x50mm
Colour	Oyster white; RAL 1013
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0692 kg CO2e / 1 Piece


Technical data sheet

Flat angle cover, for duct type WDK 13025

Item number: 6192740



Dimensions

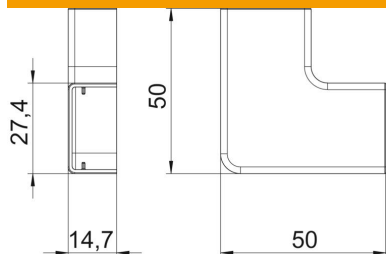

Length	50 mm
Width	25 mm
Height	13 mm
Dimension a	50 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C