


# Technical data sheet

Flat angle cover, trunking type WDK 60130

Item number: 6183433



Flat angle hood for changing the direction of the WDK trunking.

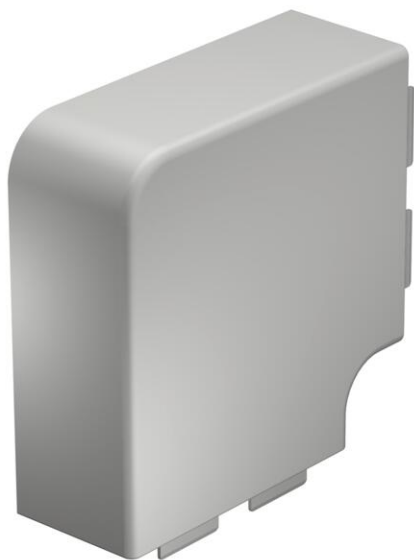

**PVC** Polyvinylchloride

## Master data

Item number	6183433
Type	WDK HF60130LGR
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	60x130mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	17.272 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3499 kg CO2e / 1 Piece

# Technical data sheet

Flat angle cover, trunking type WDK 60130

Item number: 6183433



## Dimensions



Length	170 mm
Width	130 mm
Height	60 mm
Dimension a	170 mm
Dimension H	130 mm

## Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions for duct dimension	no 60 x 130
Halogen-free	no
Trunking depth	60 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm