

Technical data sheet

T and intersection cover, for trunking type WDK 40060

Item number: 6182925



T and intersection cover for changing the direction of the WDK trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.




PVC Polyvinylchloride

Master data

Item number	6182925
Type	WDK HK40060LGR
Description 1	T- and crosspiece cover
Manufacturer	OBO
Dimension	40x60mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	9.801 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2683 kg CO2e / 1 Piece

Dimensions

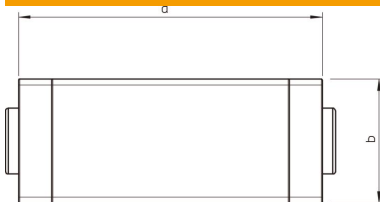

Length	190 mm
Width	65 mm
Height	40 mm
Dimension a	190 mm
Dimension b	63 mm
Dimension H	60 mm

Technical data sheet

T and intersection cover, for trunking type WDK 40060

Item number: 6182925



Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	40x60
Trunking depth	40 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C