

# Technical data sheet

## T and intersection cover, for trunking type WDK 40060

Item number: 6192556



T and intersection cover for changing the direction of the WDK trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.




**PVC** Polyvinylchloride

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 6192556                  |
| Type                               | WDK HK40060RW            |
| Description 1                      | T- and crosspiece cover  |
| Manufacturer                       | OBO                      |
| Dimension                          | 40x60mm                  |
| Colour                             | Pure white; RAL 9010     |
| Material                           | Polyvinylchloride        |
| Smallest sales unit                | 2                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 9.801 kg                 |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,2422 kg CO2e / 1 Piece |

### Dimensions

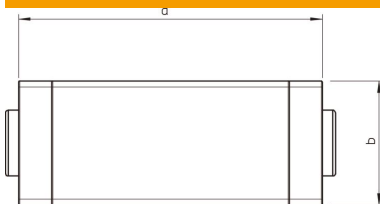

|             |        |
|-------------|--------|
| Length      | 190 mm |
| Width       | 65 mm  |
| Height      | 40 mm  |
| Dimension a | 190 mm |
| Dimension b | 63 mm  |
| Dimension H | 60 mm  |

# Technical data sheet

T and intersection cover, for trunking type WDK 40060

Item number: 6192556



## Technical data

|                                   |              |
|-----------------------------------|--------------|
| Version for                       | Hood fitting |
| Fastening type                    | Lockable     |
| Maintain electrical functions     | no           |
| for duct dimension                | 40x60        |
| Trunking depth                    | 40 mm        |
| Protection rating                 | IP30         |
| Protection rating IK code         | IK04         |
| Permitted temperature range, max. | 60 °C        |
| Permitted temperature range, min. | -5 °C        |