

Technical data sheet

T and intersection cover, for trunking type WDK 40090

Item number: 6182933



T and intersection cover for changing the direction of the WDK trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.




PVC Polyvinylchloride

Master data

Item number	6182933
Type	WDK HK40090LGR
Description 1	T- and crosspiece cover
Manufacturer	OBO
Dimension	40x90mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	13.986 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3419 kg CO2e / 1 Piece

Dimensions

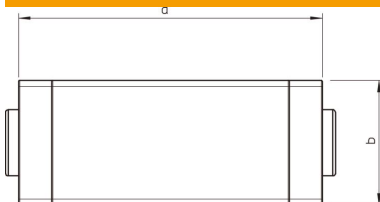

Length	230 mm
Width	90 mm
Height	40 mm
Dimension a	230 mm
Dimension b	91 mm
Dimension H	90 mm

Technical data sheet

T and intersection cover, for trunking type WDK 40090

Item number: 6182933



Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	40 x 90
Trunking depth	40 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C