

Technical data sheet

T and intersection cover, for trunking type WDK 60060

Item number: 6192610



T and intersection cover for changing the direction of the WDK trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.




PVC Polyvinylchloride

Master data

Item number	6192610
Type	WDK HK60060RW
Description 1	T- and crosspiece cover
Manufacturer	OBO
Dimension	60x60mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	12.876 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3279 kg CO2e / 1 Piece

Dimensions

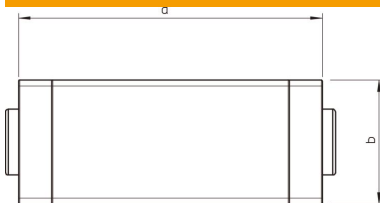

Length	190 mm
Width	60 mm
Height	60 mm
Dimension a	190 mm
Dimension b	65 mm
Dimension H	60 mm

Technical data sheet

T and intersection cover, for trunking type WDK 60060

Item number: 6192610



Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 60
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C