

# Technical data sheet

## T and intersection cover, for trunking type WDK 60130

Item number: 6192645



T and intersection cover for changing the direction of the WDK trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.




**PVC** Polyvinylchloride

### Master data

Item number	6192645
Type	WDK HK60130RW
Description 1	T- and crosspiece cover
Manufacturer	OBO
Dimension	60x130mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	23.968 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4828 kg CO2e / 1 Piece

### Dimensions

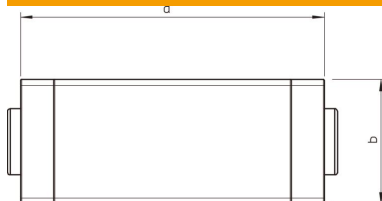

Length	272 mm
Width	130 mm
Height	60 mm
Dimension a	272 mm
Dimension b	65 mm
Dimension H	130 mm

# Technical data sheet

T and intersection cover, for trunking type WDK 60130

Item number: 6192645



## Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 130
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C