


Technical data sheet

Pipe adapter, trunking to pipe, 20 mm

Item number: 6193731

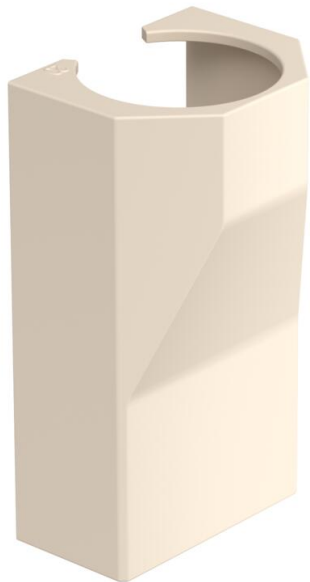

Pipe adapter for transferring an installation pipe to the WDK trunking.



PC/ABS Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6193731
Type	WDK HPC13025PW20
Description 1	Pipe adapter
Description 2	Trunking on pipe 20 mm
Manufacturer	OBO
Dimension	15x27x50mm
Colour	Oyster white; RAL 1013
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.431 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0309 kg CO2e / 1 Piece


Technical data sheet

Pipe adapter, trunking to pipe, 20 mm

Item number: 6193731



Dimensions

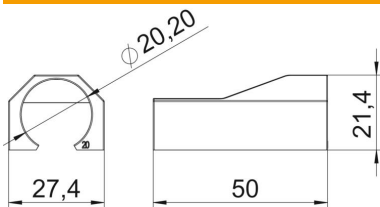

Technical data

Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C