


Technical data sheet

Joint cover, for trunking, type WDK 10030

Item number: 6154034



Joint cover for smooth connection of trunking segments.

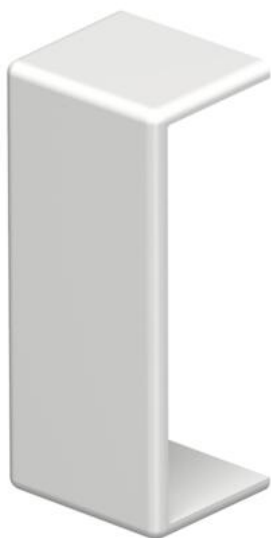

PVC Polyvinylchloride

Master data

Item number	6154034
Type	WDK HS10030RW
Description 1	Joint cover
Manufacturer	OBO
Dimension	10x30mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.115 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0063 kg CO2e / 1 Piece


Technical data sheet

Joint cover, for trunking, type WDK 10030

Item number: 6154034



Dimensions

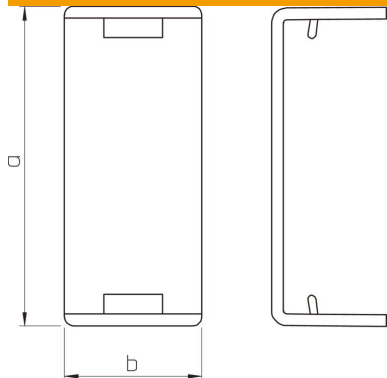

Length	14 mm
Width	32 mm
Height	10 mm
Dimension a	32 mm
Dimension b	14 mm
Dimension H	30 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
for duct dimension	10x30
Halogen-free	no
Trunking depth	10 mm
Cover width	14 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C