


Technical data sheet

Joint cover, for trunking, type WDK 13025

Item number: 6193496

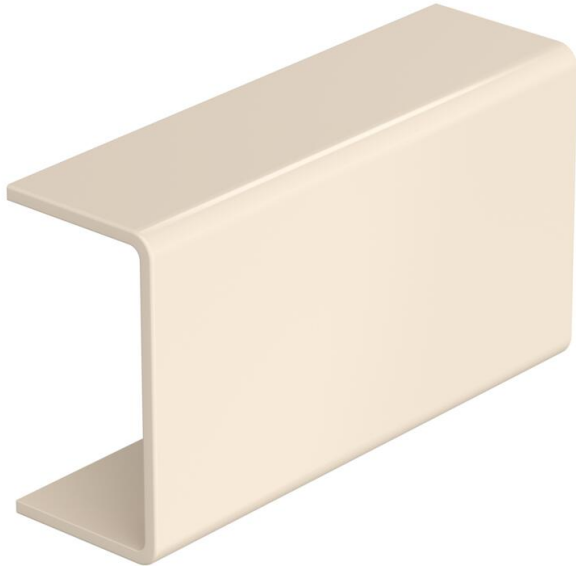

Joint cover for perfect connection of the WDK trunking segments, type 13025. Incl. coupling for the raised trunking floor.




PC/ABS Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6193496
Type	WDK HS13025PW
Description 1	Joint cover
Description 2	with coupling for raised floor
Manufacturer	OBO
Dimension	15x27x50mm
Colour	Oyster white; RAL 1013
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	20
Unit of quantity	Piece
Weight	0.556 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0552 kg CO2e / 1 Piece

Dimensions

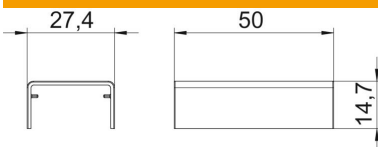

Length	50 mm
Width	27.4 mm
Height	14.7 mm

Technical data sheet

Joint cover, for trunking, type WDK 13025

Item number: 6193496



Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C