

Technical data sheet

Joint cover, for trunking, type WDK 13025

Item number: 6193498



Joint cover for perfect connection of the WDK trunking segments, type 13025. Incl. coupling for the raised trunking floor.




PC/ABS Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

| | |
|------------------------------------|--|
| Item number | 6193498 |
| Type | WDK HS13025RW |
| Description 1 | Joint cover |
| Description 2 | with coupling for raised floor |
| Manufacturer | OBO |
| Dimension | 15x27x50mm |
| Colour | Pure white; RAL 9010 |
| Material | Polycarbonate/Acrylnitrile-butadiene-styrene |
| Smallest sales unit | 20 |
| Unit of quantity | Piece |
| Weight | 0.556 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0701 kg CO2e / 1 Piece |

Dimensions

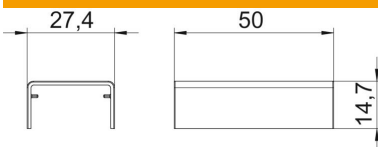

| | |
|--------|---------|
| Length | 50 mm |
| Width | 27.4 mm |
| Height | 14.7 mm |

Technical data sheet

Joint cover, for trunking, type WDK 13025

Item number: 6193498



Technical data

| | |
|-----------------------------------|--------------------|
| Version for | Trunking cut cover |
| Fastening type | Lockable |
| Shape | Symmetrical |
| Halogen-free | no |
| Protection rating | IP30 |
| Protection rating IK code | IK04 |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -5 °C |