


# Technical data sheet

Joint cover, for trunking, type WDK 20050

Item number: 6154069



Joint cover for smooth connection of trunking segments.

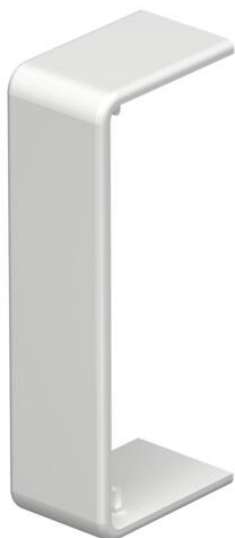

**PVC** Polyvinylchloride

## Master data

Item number	6154069
Type	WDK HS20050RW
Description 1	Joint cover
Manufacturer	OBO
Dimension	20x50mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.267 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0117 kg CO2e / 1 Piece


# Technical data sheet

Joint cover, for trunking, type WDK 20050

Item number: 6154069



## Dimensions

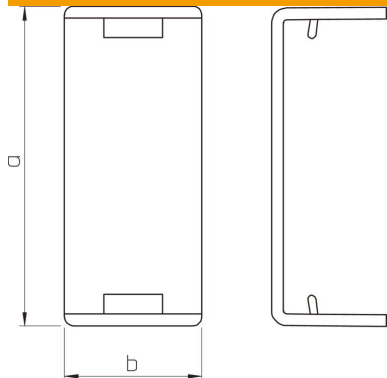

Length	14 mm
Width	53 mm
Height	20 mm
Dimension a	53 mm
Dimension b	14 mm
Dimension H	50 mm

## Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
for duct dimension	20x50
Halogen-free	no
Trunking depth	20 mm
Cover width	14 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C