


Technical data sheet

Joint cover, for trunking, type WDK 25040

Item number: 6158889



Joint cover for smooth connection of trunking segments.

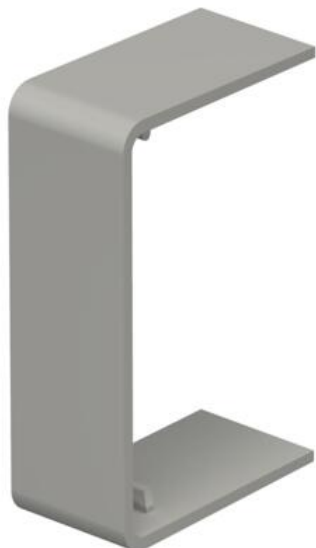

PVC Polyvinylchloride

Master data

Item number	6158889
Type	WDK HS25040GR
Description 1	Joint cover
Manufacturer	OBO
Dimension	25x40mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.231 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0102 kg CO2e / 1 Piece


Technical data sheet

Joint cover, for trunking, type WDK 25040

Item number: 6158889



Dimensions

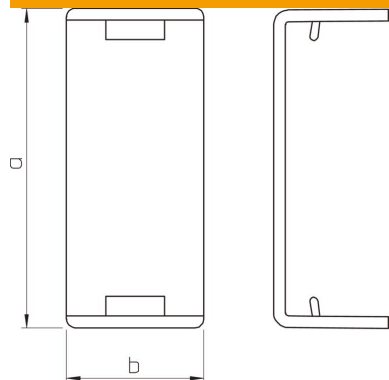

Length	14 mm
Width	42 mm
Height	25 mm
Dimension a	42 mm
Dimension b	14 mm
Dimension H	40 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
for duct dimension	25x40
Halogen-free	no
Trunking depth	25 mm
Cover width	14 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C