

Technical data sheet

Joint cover, for trunking, type WDK 40090

Item number: 6193582



Joint cover for hiding cut edges and for smooth connection of trunking segments.



PVC Polyvinylchloride

Master data

Item number	6193582
Type	WDK HS40090CW
Description 1	Joint cover
Description 2	for WDK 40090
Manufacturer	OBO
Dimension	42x93x18mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	20
Unit of quantity	Piece
Weight	0.857 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0313 kg CO2e / 1 Piece


Technical data sheet

Joint cover, for trunking, type WDK 40090

Item number: 6193582



Dimensions

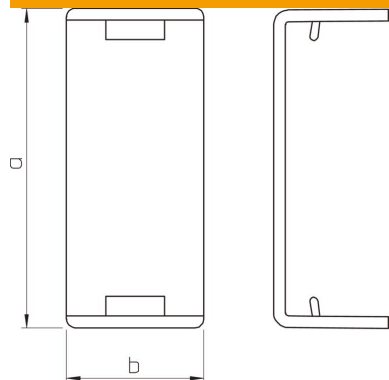

Length	18 mm
Width	90 mm
Height	39 mm
Dimension a	90 mm
Dimension b	39 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Cover width	39 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C