

Technical data sheet

T piece cover, for trunking type WDK 10020

Item number: 6154115



T piece hood for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6154115
Type	WDK HT10020RW
Description 1	T piece hood
Manufacturer	OBO
Dimension	10x20mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	0.334 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0211 kg CO2e / 1 Piece


Technical data sheet

T piece cover, for trunking type WDK 10020

Item number: 6154115



Dimensions

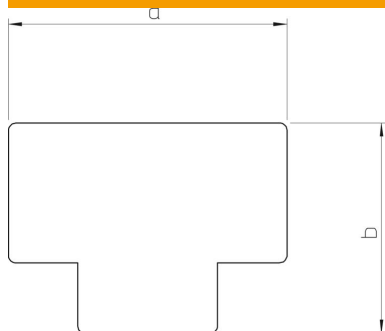

Length	45 mm
Width	22 mm
Height	10 mm
Dimension a	45 mm
Dimension b	34 mm
Dimension H	20 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	10 x 20
Halogen-free	no
Trunking depth	10 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C