


# Technical data sheet

## T piece cover, for trunking type WDK 10030

Item number: 6154123



T piece cover for changing the direction of the WDK trunking.

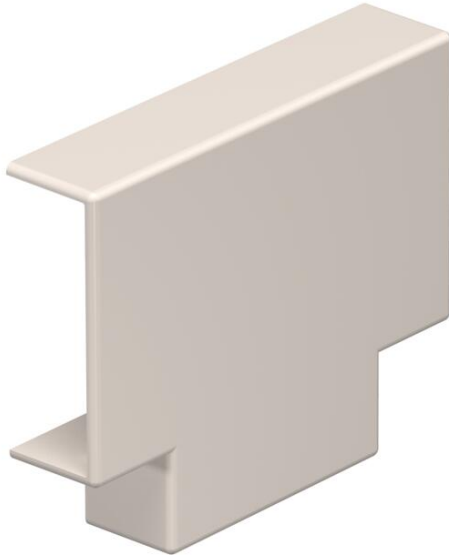

**PVC** Polyvinylchloride

### Master data

Item number	6154123
Type	WDK HT10030RW
Description 1	T piece hood
Manufacturer	OBO
Dimension	10x30mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	0.455 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,018 kg CO2e / 1 Piece


# Technical data sheet

T piece cover, for trunking type WDK 10030

Item number: 6154123



## Dimensions

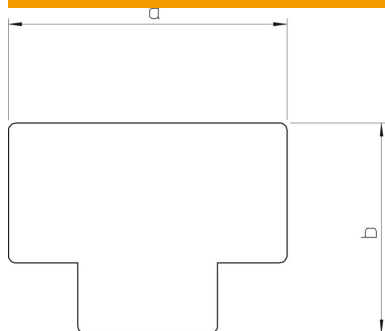

Length	55 mm
Width	30 mm
Height	10 mm
Dimension a	55 mm
Dimension b	44 mm
Dimension H	30 mm

## Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	10 x 30
Halogen-free	no
Trunking depth	10 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C