

Technical data sheet

T piece cover, for trunking type WDK 13025

Item number: 6192449



T piece cover for changing the direction of the WDK trunking.



PC/ABS Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6192449
Type	WDK HT13025PW
Description 1	T piece hood
Description 2	with coupling for raised floor
Manufacturer	OBO
Dimension	15x73x50mm
Colour	Oyster white; RAL 1013
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	1.059 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,099 kg CO2e / 1 Piece


Technical data sheet

T piece cover, for trunking type WDK 13025

Item number: 6192449



Dimensions

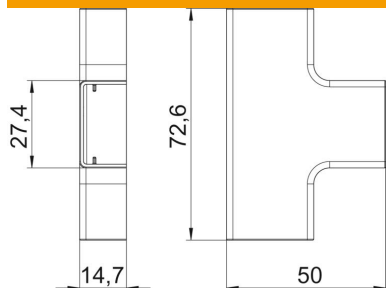

Length	72 mm
Width	25 mm
Height	13 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C