


Technical data sheet

T piece cover, for trunking type WDK 15030

Item number: 6161928



T piece cover for changing the direction of the WDK trunking.

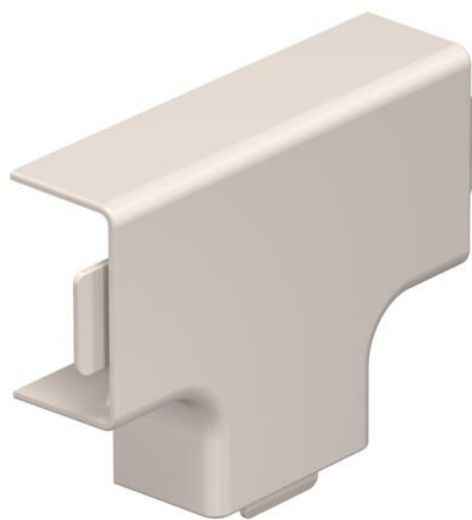

PVC Polyvinylchloride

Master data		
Item number	6161928	
Type	WDK HT15030CW	
Description 1	T piece hood	
Manufacturer	OBO	
Dimension	15x30mm	
Colour	Cream; RAL 9001	
Material	Polyvinylchloride	
Smallest sales unit	4	
Unit of quantity	Piece	
Weight	1.119 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0538 kg CO2e / 1 Piece	


Technical data sheet

T piece cover, for trunking type WDK 15030

Item number: 6161928



Dimensions

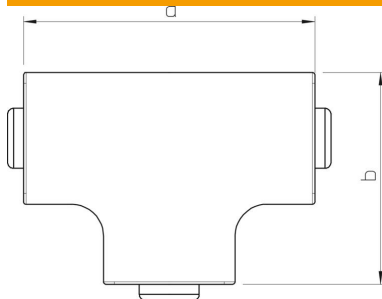

Length	73 mm
Width	30 mm
Height	18.5 mm
Dimension a	73 mm
Dimension b	53 mm
Dimension H	30 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	15 x 30
Halogen-free	no
Trunking depth	15 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C