

# Technical data sheet

## T piece cover, for trunking type WDK 15040

Item number: 6192467



T piece cover for changing the direction of the WDK trunking.



**PVC** Polyvinylchloride

### Master data

Item number	6192467
Type	WDK HT15040RW
Description 1	T piece hood
Manufacturer	OBO
Dimension	15x40mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	1.746 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0686 kg CO2e / 1 Piece


# Technical data sheet

T piece cover, for trunking type WDK 15040

Item number: 6192467



## Dimensions

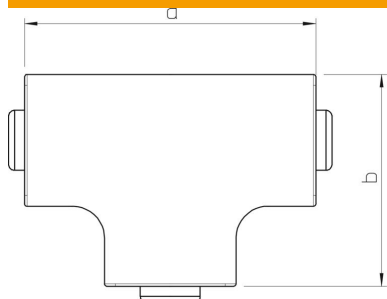

Length	83 mm
Width	40 mm
Height	15 mm
Dimension a	83 mm
Dimension b	74 mm
Dimension H	40 mm

## Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	15 x 40
Halogen-free	no
Trunking depth	15 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C