

Technical data sheet

T piece cover, for trunking type WDK 20020

Item number: 6182801



T piece cover for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6182801
Type	WDK HT20020LGR
Description 1	T piece hood
Manufacturer	OBO
Dimension	20x20mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	0.751 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0253 kg CO2e / 1 Piece


Technical data sheet

T piece cover, for trunking type WDK 20020

Item number: 6182801



Dimensions

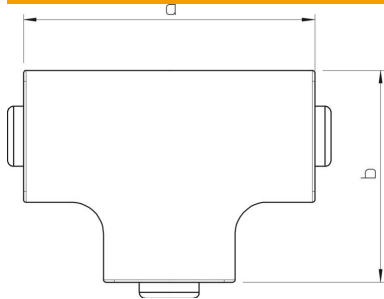

Length	57 mm
Width	20 mm
Height	20 mm
Dimension a	57 mm
Dimension b	39 mm
Dimension H	20 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	20 x 20
Halogen-free	no
Trunking depth	20 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C