


Technical data sheet

T piece cover, for trunking type WDK 25025

Item number: 6192483



T piece cover for changing the direction of the WDK trunking.

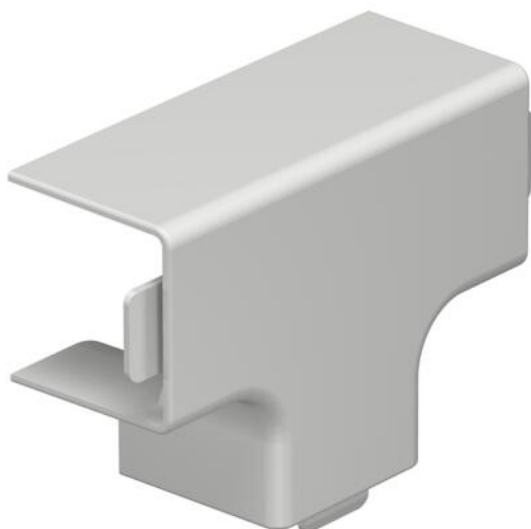

PVC Polyvinylchloride

Master data

Item number	6192483
Type	WDK HT25025RW
Description 1	T piece hood
Manufacturer	OBO
Dimension	25x25mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	1.171 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0582 kg CO2e / 1 Piece


Technical data sheet

T piece cover, for trunking type WDK 25025

Item number: 6192483



Dimensions

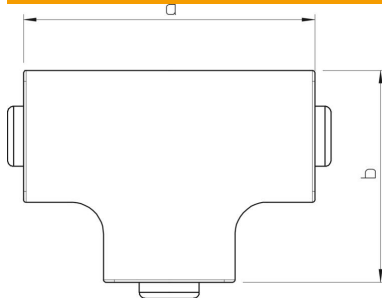

Length	68 mm
Width	25 mm
Height	25 mm
Dimension a	68 mm
Dimension b	48 mm
Dimension H	25 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	25 x 25
Halogen-free	no
Trunking depth	25 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C