


Technical data sheet

T piece cover, for trunking type WDK 30045

Item number: 6182895



T-piece cover for changing the direction of the WDK trunking.

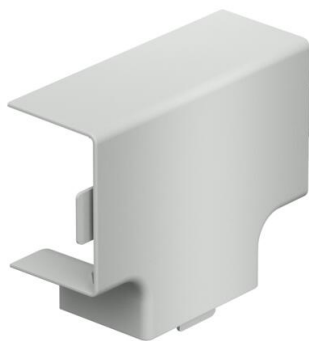

PVC Polyvinylchloride

Master data

Item number	6182895
Type	WDK HT30045LGR
Description 1	T piece hood
Manufacturer	OBO
Dimension	30x45mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	2.003 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0653 kg CO2e / 1 Piece


Technical data sheet

T piece cover, for trunking type WDK 30045

Item number: 6182895



Dimensions

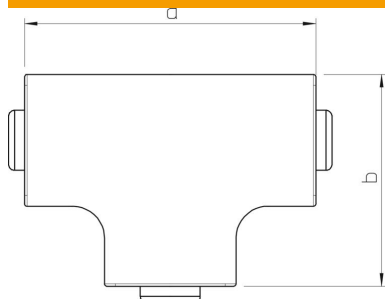

Length	88 mm
Width	45 mm
Height	30 mm
Dimension a	88 mm
Dimension b	68 mm
Dimension H	45 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	30 x 45
Halogen-free	no
Trunking depth	30 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C