


Technical data sheet

T and intersection cover, for trunking type WDK 40040

Item number: 6161995

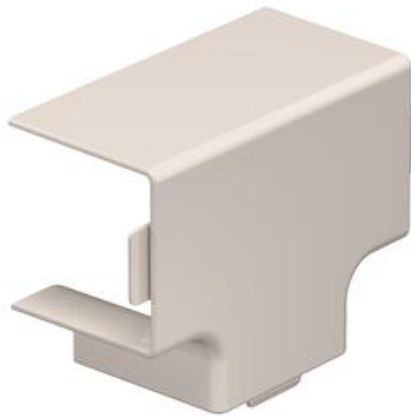

T and intersection cover for changing the direction of the WDK trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.



PVC Polyvinylchloride

Master data

Item number	6161995
Type	WDK HT40040CW
Description 1	T- and crosspiece cover
Manufacturer	OBO
Dimension	40x40mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	2.681 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0809 kg CO2e / 1 Piece


Technical data sheet

T and intersection cover, for trunking type WDK 40040

Item number: 6161995



Dimensions

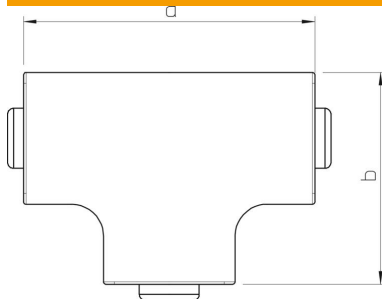

Length	83 mm
Width	40 mm
Height	40 mm
Dimension a	83 mm
Dimension b	43 mm
Dimension H	40 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	40 x 40
Trunking depth	40 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C